


# Plug NECU-S1W9-C2-ACO

Part number: 574588

FESTO

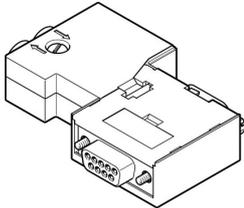

## Data sheet

Feature	Value
Type code	NECU
Type of mounting	4-40 UNC-2B
Fieldbus interface	Sub-D, 9-pin, socket
Electrical connection 1	Socket, Sub-D, 9-pin
Electrical connection 2	Screw terminal, can be shielded
Baud rate	1 Mbit/s
Approved cable diameter	8 mm
Approved cable diameter	8 mm
Connection cross section	0.14 mm <sup>2</sup> ... 0.5 mm <sup>2</sup>
Degree of protection	IP20
Ambient temperature	-20 °C ... 70 °C
Relative air humidity	75 % at 25 °C
Note on materials	RoHS-compliant
Corrosion resistance class (CRC)	1 - Low corrosion stress
Housing material	PC-reinforced