


## Sub-base VMPAC-AP-14-B-1

Part number: 576574

FESTO

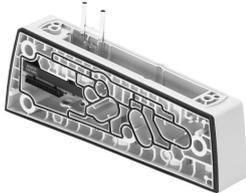

### Data sheet

Feature	Value
Width	32.8 mm
Length	169 mm
Width dimension	26.8 mm
Type code	VMPAC
Max. no. of valve positions	1
Operating pressure	-0.9 bar ... 8 bar
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	160 g
Pneumatic connection 2	G1/4
Pneumatic connection 4	G1/4
Note on materials	RoHS-compliant
Housing material	PA-reinforced