


Rod clevis
SG-M10X1,25
Part number: 6144

FESTO

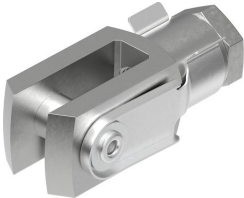

Data sheet

Feature	Value
Size	M10x1.25
Type code	SG
Conforms to standard	DIN 71752 ISO 8140
Threaded connection	Internal thread M10x1.25
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-40 °C ... 150 °C
Product weight	103 g
Note on materials	Free of copper and PTFE RoHS-compliant
Bolt material	Steel Galvanized
Clevis material	Steel Galvanized
Nut material	Steel Galvanized