


Pneumatic muffler U-3/4-B

Part number: 6845

FESTO

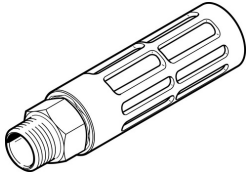

Data sheet

Feature	Value
Type code	U
Mounting position	Any
Symbol	00991473
Operating pressure for entire temperature range	0 bar ... 10 bar
Flow rate with respect to atmosphere	10000 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
Noise level	83 dB(A)
Ambient temperature	-10 °C ... 70 °C
Product weight	120 g
Pneumatic connection	G3/4
Cushioning insert material	PE
Material of screwed trunnion	Aluminum
Note on materials	Free of copper and PTFE RoHS-compliant
Housing material	Aluminum