


Pressure gauge MA-63-0,25

Part number: 7169

FESTO

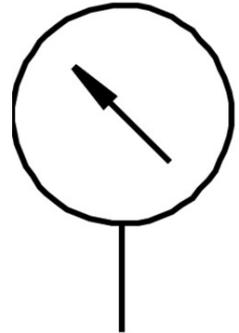

Data sheet

Feature	Value
Display range	0 bar ... 0.25 bar
Display range	0 psi ... 3.6 psi
Type code	MA
Symbol	00991463
Conforms to standard	DIN EN 837-3
Pressure gauge nominal size	63
Explosion prevention and protection	Observe the information on the certificate Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Type of mounting	Line installation
Operating medium	Liquid media Gaseous media
Operating pressure	0 bar ... 0.25 bar
Intermittent load factor	0.9
Continuous load factor	0.75
Measurement accuracy class	1.6
Degree of protection	IP43
Temperature of medium	-20 °C ... 80 °C
Ambient temperature	-20 °C ... 60 °C
Connection position	Centered on rear side
Pneumatic connection	G1/4
Material of screwed trunnion	Brass
Housing material	Steel
Inspection window material	PMMA
Product weight	180 g
Information on operating and pilot media	No acetylene No oxygen