 



# Vertical pressure supply plate VABF-S4-1-P1A14-N14

FESTO

Part number: 8000690

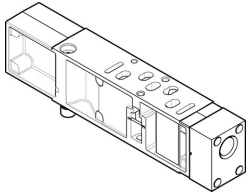

## Data sheet

Feature	Value
Width	26 mm
Type code	VABF
Based on norm	ISO 15407-2
Mounting position	Any
Pneumatic vertical stacking	Alternative pressure supply for 1 and 14
Symbol	00992919
Operating pressure	1 MPa
Operating pressure	10 bar
Standard nominal flow rate	900 l/min
CE marking (see declaration of conformity)	As per EU low voltage directive
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C ... 50 °C
Product weight	191 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pneumatic connection 1	1/4 NPT
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum