


# Sub-base VMPA14-IC-AP-S-1

Part number: 8023667

FESTO

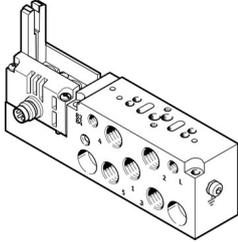

## Data sheet

Feature	Value
Width	24.4 mm
Length	107.3 mm
Width dimension	14.9 mm
Type code	VMPA14
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Certification	c UL us - Recognized (OL)
KC characters	KC EMC
CE marking (see declaration of conformity)	As per EU EMC directive
Corrosion resistance class (CRC)	0 - No corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	150 g
Electrical connection	M8 Plug
Sub-base mounting type	With through-hole
Pilot air port 12/14	M5
Pilot exhaust air port 82/84	M5
Pneumatic connection 1	G1/8 M7
Pneumatic connection 2	G1/8 M7
Pneumatic connection 3	M7 G1/8
Pneumatic connection 4	G1/8 M7
Pneumatic connection 5	G1/8 M7
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum