


Flow control VFFG-T-M5-10

Part number: 8025713

FESTO

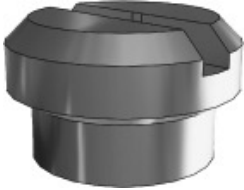

Data sheet

Feature	Value
Type code	VFFG
Valve function	Flow control function
Type of mounting	With thread
Standard nominal flow rate in flow control direction	40.8 l/min
Operating pressure	-0.9 bar ... 10 bar
Ambient temperature	-5 °C ... 60 °C
Nominal width	1.05 mm
b-value	0.5
C value	0.14 l/sbar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Storage temperature	-20 °C ... 60 °C
Product weight	0.5 g
Note on materials	RoHS-compliant
Hollow bolt material	PA