


Sub-base
VMPA2-FB-AP-2-1-T0-RV
Part number: 8034550

FESTO

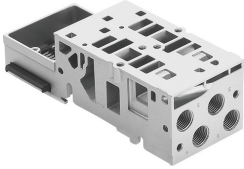

Data sheet

Feature	Value
Width	52 mm
Length	107.3 mm
Width dimension	21 mm
Type code	VMPA2
Max. no. of valve positions	2
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Corrosion resistance class (CRC)	0 - No corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	190 g
Note on materials	RoHS-compliant
Material of sub-base	Die-cast aluminum