


Sub-base VMPAL-AP-14-T135-RV

Part number: 8034560

FESTO

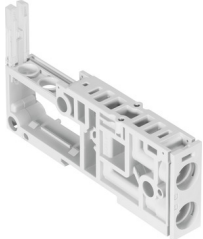

Data sheet

Feature	Value
Width	14 mm
Width	14.9 mm
Length	107.3 mm
Width dimension	14.9 mm
Type code	VMPAL
Pressure zone separation	Channels 1, 3 and 5
Integrated function	Non-return valve
Max. no. of valve positions	1
Flow direction	Non-reversible
Valve manifold design	Valve sizes can be mixed
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Suitability for vacuum	no
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	3 - High corrosion stress
Ambient temperature	-5 °C ... 50 °C
Product weight	35 g
Pneumatic connection 2	for 14 mm cartridge
Pneumatic connection 4	For 14 mm cartridge
Note on materials	RoHS-compliant
Material of sub-base	PA-reinforced