


# Braking resistor CACR-LE2-6-W60

Part number: 8047913

FESTO

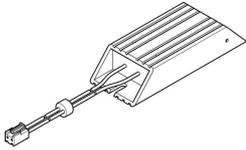

## Data sheet

Feature	Value
Size	60
Type code	CACR
Mounting position	Free convection Vertical Horizontal
Output at 35% duty cycle and 20°C	180 W
Braking resistor nominal power	60 W
Resistance value	6 Ohm
Certification	c UL us - Recognized (OL)
Degree of protection	IP65
Ambient temperature	0 °C ... 50 °C
Product weight	140 g
Type of mounting	With through-hole
Note on materials	Contains paint-wetting impairment substances RoHS-compliant