


Parallel kit EAMM-U-70-S48-60RA-96

Part number: 8058969

FESTO

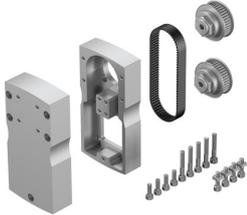

Data sheet

Feature	Value
Size	70
Type code	EAMM-U
Mounting position	Any
Max. rotational speed	5000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	118 kgmm ²
No-load driving torque	0.18 Nm
Transferable torque	7 Nm
Product weight	1800 g
Interface code, actuator	S48
Interface code, motor in	60RA
Note on materials	RoHS-compliant