


Parallel kit EAMM-U-86-S48-70AA-177

Part number: 8059017

FESTO

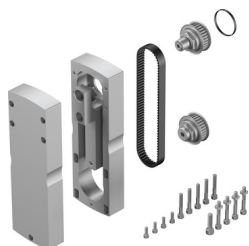

Data sheet

Feature	Value
Size	86
Type code	EAMM-U
Mounting position	Any
Max. rotational speed	5000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	175 kgmm ²
No-load driving torque	0.25 Nm
Transferable torque	9.5 Nm
Product weight	3300 g
Interface code, actuator	S48
Interface code, motor in	70AA
Note on materials	RoHS-compliant