


Axial kit
EAMM-A-L38-70AA
Part number: 8063461

FESTO

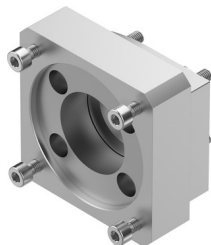

Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	9 Nm
Product weight	418 g
Interface code, actuator	L38
Interface code, motor in	70AA 70AB
Note on materials	RoHS-compliant