


**Axial kit**  
**EAMM-A-L48-90GB**  
Part number: 8063488

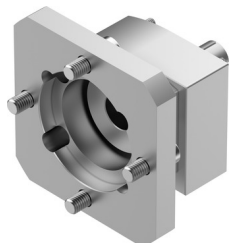

**Data sheet**

| Feature                  | Value            |
|--------------------------|------------------|
| Type code                | EAMM-A           |
| Mounting position        | Any              |
| Storage temperature      | -25 °C ... 60 °C |
| Relative air humidity    | 0 - 95 %         |
| Degree of protection     | IP40             |
| Ambient temperature      | -10 °C ... 60 °C |
| Transferable torque      | 17 Nm            |
| Product weight           | 790 g            |
| Interface code, actuator | L48              |
| Interface code, motor in | 90GB             |
| Note on materials        | RoHS-compliant   |