


Axial kit
EAMM-A-N38-56GA
Part number: 8063585

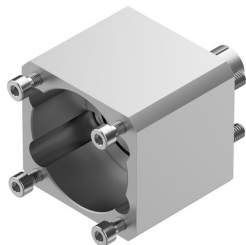

Data sheet

Feature	Value
Type code	EAMM-A
Mounting position	Any
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transferable torque	12.5 Nm
Product weight	512 g
Interface code, actuator	N38
Interface code, motor in	56GA
Note on materials	RoHS-compliant