


# Ball valve actuator unit VZBM-A-11/4"-RP-25-D-2-B2-PB20

FESTO

Part number: 8070247

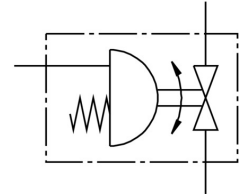

## Data sheet

Feature	Value
Type code	VZBM
Structural design	2-way ball valve Quarter turn actuator
Actuation type	Pneumatic
Mounting position	Any
Type of mounting	Line installation
Fitting connection	Rp1 1/4
Switching position indication	Slot direction = flow direction
Nominal width DN	32
Operating pressure	5.5 bar ... 8 bar
Nominal pressure of fitting PN	25
Symbol	00992011
Medium	Compressed air as per ISO 8573-1:2010 [-:-:-] Inert gas Water – no water vapor Neutral liquids
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Temperature of medium	-15 °C ... 90 °C
Ambient temperature	-20 °C ... 80 °C
Flow rate Kv	84 m <sup>3</sup> /h
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Housing material	Brass, nickel-plated
Material number of housing	CW617N
Seals material	FPM HNBR PTFE
Ball material	Brass, chrome-plated
Material number for ball	CW614N
Shaft material	Brass
Material number for shaft	CW614N
Product weight	2157 g
Corrosion resistance class (CRC)	1 - Low corrosion stress