


Ball valve actuator unit VZBM-A-3/8"-RP-25-F-3T-B2-PA10

Part number: 8070259

FESTO

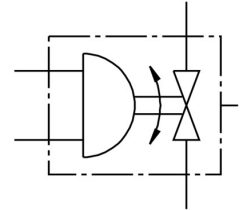

Data sheet

Feature	Value
Type code	VZBM
Structural design	3-way ball valve Quarter turn actuator
Actuation type	Pneumatic
Mounting position	Any
Type of mounting	Line installation
Fitting connection	Rp3/8
Switching position indication	Slot direction = flow direction
Nominal width DN	10
Operating pressure	5.5 bar ... 8 bar
Nominal pressure of fitting PN	25
Symbol	00991921
Medium	Compressed air as per ISO 8573-1:2010 [-:-:-] Inert gas Water – no water vapor Neutral liquids
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Temperature of medium	-20 °C ... 130 °C
Ambient temperature	-20 °C ... 80 °C
Flow rate Kv type T corner	9.4 m³/h
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Housing material	Brass, nickel-plated
Material number of housing	CW617N
Seals material	HNBR PTFE
Ball material	Brass, chrome-plated
Material number for ball	CW614N
Shaft material	Brass
Material number for shaft	CW614N
Product weight	1441 g
Corrosion resistance class (CRC)	1 - Low corrosion stress