
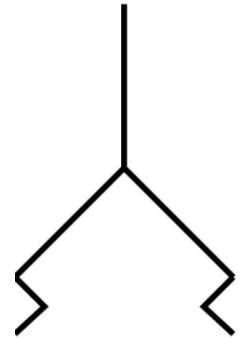


Vacuum suction cup OGVM-30X65-AV-HN-G14F

Part number: 8073869

FESTO

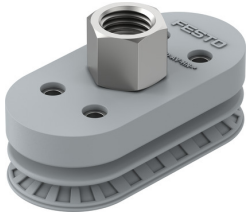

Data sheet

Feature	Value
Suction cup height compensation	7 mm
Min. workpiece radius	15 mm
Nominal width	6 mm
Vacuum cup size	30x65 mm
Suction cup volume	11.5 cm ³
Type code	OGVM
Connection position	Top
Mounting position	Any
Symbol	00991485
Suction cup shape	oval bellows 1.5-fold
Operating pressure	-0.95 bar ... 0 bar
Nominal operating pressure	-0.6 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	10 °C ... 120 °C
Holding force at nominal operating pressure	75 N
Vertical lateral force at nominal operating pressure	75 N
Product weight	48 g
Type of mounting	Via vacuum connection
Vacuum connection	G1/4
Color	Gray
Shore hardness	60 +/- 5
Material of screwed trunnion	Wrought aluminum alloy
Note on materials	RoHS-compliant
Suction cup material	HNBR