


Manifold rail

VABM-P7-18MB-G18-M5-8

Part number: 8076391

FESTO

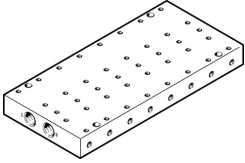

Data sheet

Feature	Value
Width dimension	18 mm
Type code	VABM
Structural design	Connection direction downwards
Max. no. of valve positions	8
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS conformity	VDMA24364-B2-L
Max. tightening torque for valve mounting	0.6 Nm
Product weight	360 g
Pneumatic connection 1	G1/8
Pneumatic connection 2	M5
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy