


Axial kit EAMM-A-T46-67A

Part number: 8084495

FESTO

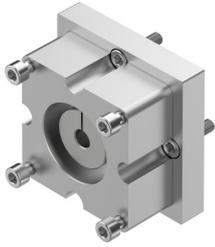

Data sheet

| Feature | Value |
|--------------------------|-----------------------|
| Nominal length | 42 mm |
| Type code | EAMM-A |
| Mounting position | Any |
| Max. rotational speed | 8000 1/min |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 3.2 kgmm ² |
| Transferable torque | 8.5 Nm |
| Product weight | 478 g |
| Interface code, actuator | T46 |
| Interface code, motor in | 67A |
| Note on materials | RoHS-compliant |