


# Pressure gauges PAGN-23-10-G18S

Part number: 8088991

FESTO

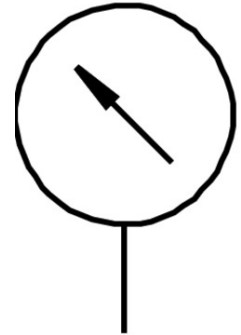

## Data sheet

Feature	Value
Display range	0 bar ... 10 bar
Type code	PAGN
Symbol	00991463
Pressure gauge nominal size	23
Structural design	Bourdon tube pressure gauge
Type of mounting	Line installation
Operating medium	Inert gas Neutral liquids
Operating pressure	0 MPa ... 1 MPa
Operating pressure	0 bar ... 10 bar
Operating pressure	0 psi ... 145 psi
Intermittent load factor	0.6
Measurement accuracy class	4
Degree of protection	IP44
Storage temperature	-5 °C ... 50 °C
Temperature of medium	-5 °C ... 50 °C
Ambient temperature	-5 °C ... 50 °C
Note on materials	RoHS-compliant
Connection position	Centered on rear side
Pneumatic connection	G1/8 with sealing ring
Materials in contact with the media	ABS-reinforced Brass
Material of screwed trunnion	ABS-reinforced
Housing material	ABS
Inspection window material	PMMA
Housing colour	Black
Product weight	6 g
Information on operating and pilot media	No acetylene No oxygen