


Braking resistor CACR-LE2-240-W500

Part number: 8091543

FESTO

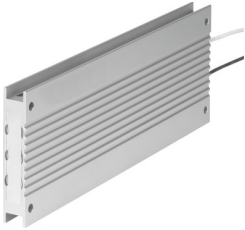

Data sheet

Feature	Value
Size	500
Type code	CACR
Mounting position	Free convection Vertical
Pulse energy braking resistor at 380 V	2000 Ws
Pulse energy braking resistor at 780 V	1800 Ws
Output at 35% duty cycle and 20°C	500 W
Braking resistor nominal power	200 W
Braking resistor nominal power at 380 V	150 W
Braking resistor nominal power at 780 V	120 W
Resistance value	240 Ohm
Certification	c CSA us (OL) c UL us - Recognized (OL)
LABS conformity	VDMA24364 zone III
Degree of protection	IP65
Ambient temperature	0 °C ... 50 °C
Product weight	550 g
Type of mounting	Optionally: With through-hole With accessories
Note on materials	Contains paint-wetting impairment substances RoHS-compliant