


Adaptive shape gripper DHEF-20-A

FESTO

Part number: 8092533

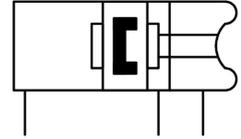

Data sheet

Feature	Value
Size	20
Shaped handle cap version	Standard
Stroke	66 mm
Min. diameter to be gripped	12 mm
Max. diameter to be gripped	38 mm
Type code	DHEF
Mounting position	Any
Mode of operation	Double-acting
Gripper function	Adaptive
Structural design	Inverting cap Positively driven motion sequence
Guide	Basic guide
Position sensing	For proximity sensor
Symbol	00997278
Operating pressure of actuator	1 bar ... 8 bar
Operating pressure of cap	0.07 bar ... 0.1 bar
Burst pressure of cap	0.3 bar
Max. operating frequency of pneumatic gripper	1 Hz
Retracting time	290 ms
Advancing time	270 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication not possible
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
For use in the food industry	See supplementary material information
Ambient temperature	0 °C ... 60 °C
Mass moment of inertia	1.29 kgcm ²
Guide value for payload	1 kg
Product weight	475 g
Type of mounting	as per ISO 9409
Pneumatic connection	M5
Note on materials	Contains paint-wetting impairment substances RoHS-compliant
Cap material	VMQ (silicone)
Housing material	Aluminum, anodized