


# Axial kit EAMM-A-T46-80PB

Part number: 8096175

FESTO

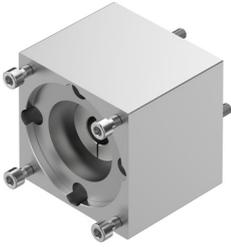

## Data sheet

Feature	Value
Nominal length	68.5 mm
Type code	EAMM-A
Mounting position	Any
Max. rotational speed	8000 1/min
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	7.65 kgmm <sup>2</sup>
Transferable torque	10 Nm
Product weight	923 g
Interface code, actuator	T46
Interface code, motor in	80PB 80R
Note on materials	RoHS-compliant