




BC Clamp

Beam Clamps 1 to 10 Metric ton Capacity

FEATURES

- ▶ 5:1 design factor for use with powered or manual hoist.
- ▶ The easy way to install a fixed hoist mount or rigging point.
- ▶ Simple installation by hand, no tools required.
- ▶ Compact and portable low headroom design.
- ▶ Available with (BCD model) or without (BC model) a movable shackle.
- ▶ “Theatrical Black” color. All parts are a matte black color.
- ▶ Meets OSHA, ASME B30, NASA-STD-8719.9 and EU Directives: 2006/42/EC

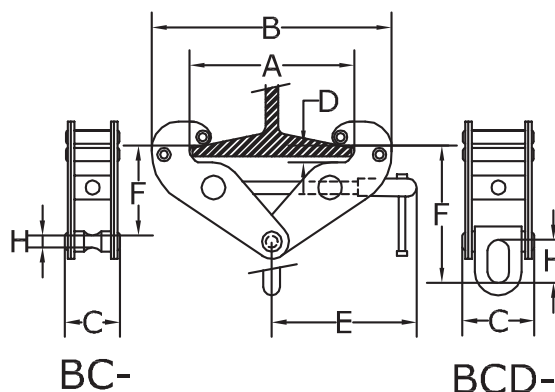

SPECIFICATION (Inches & Lbs)		(WLL) Capacity from Vertical				A" Adjustment	B" Max	C"	D"	E"	F" Max	H"	Weight Lbs.
		@0°	@15°	@30°	@45°								
1t	BC-01	2,200	0	0	0	3.1 - 9.6	14.6	3.7	0.75	7.8	5.6	0.8	7.7
	BCD-01	2,200	1,800	1,500	1,100						7.8	1.7	9.0
2t	BC-02	4,400	0	0	0	3.1 - 9.6	14.6	4.0	0.75	7.8	5.6	0.8	9.9
	BCD-02	4,400	3,700	2,900	2,200						7.8	1.7	11.00
3t	BC-03	6,600	0	0	0	3.5 - 13.0	19.7	5.2	1.12	10.4	7.8	0.9	20.9
	BCD-03	6,600	5,500	4,400	3,300						10.9	2.4	22.4
5t	BC-05	11,000	0	0	0	3.5 - 13.0	19.7	5.6	1.41	10.4	8.2	0.9	24.2
	BCD-05	11,000	9,100	7,300	5,500						10.9	2.4	26.2
10t	BC-10	22,000	0	0	0	3.5 - 13.8	20.6	7.1	1.50	11.2	8.4	1.5	35.2
	BCD-10	22,000	18,300	14,500	11,000						11.9	3.6	40.5



Before using these products; read and follow instructions in the operator's manual. Never exceed capacity. Do not use for lifting people or loads over people.