

APPLICATION:

PRODUCT NAME: CTL VLV 8AWLH RIG

JOB NAME:

☐ SPECIAL CONFIGURATION
☐ CHECK BASE MODEL AND OPTIONS

QUANTITY:

ITEM NO.:

MODEL:

- ☐ 2200 CTL VLV 8AWLH RIG SV
☐ 2200-CV CTL VLV 8AWLH RIG CK

OPTIONS OR MODIFICATIONS:

- ☐ SUPPLY LINES 36"
☐ NIPPLES
☐ ELBOWS
☐ HANDLES (CROSS OR WRIST) CIRCLE STYLE
☐ VANDAL RESISTANT KIT
☐ OTHER _____

FEATURES

CONTROL VALVE

- * ECCENTRICS ADJUST FROM 7-1/2" TO 8-1/2"
- * SWIVELLING SEAT DISKS
- * HOT SIDE STEM - RIGHT HAND
- * COLD SIDE STEM - LEFT HAND
- * STAINLESS STEEL SEATS
- * STAINLESS STEEL SEAT SCREWS
- * STAINLESS STEEL HANDLE SCREWS

SYSTEM LIMITS


- * TEMP: 40°F MIN. TO 160°F MAX.
- * PRESSURE: 200 PSI MAX. STATIC

SHIPPING WEIGHT


- * 4.0 LBS

PRODUCT COMPLIANCE:

- * ASME A112.18.1 / CSA B125.1
- * NSF 61 - Section 9
- * NSF 372 (Low Lead Content)

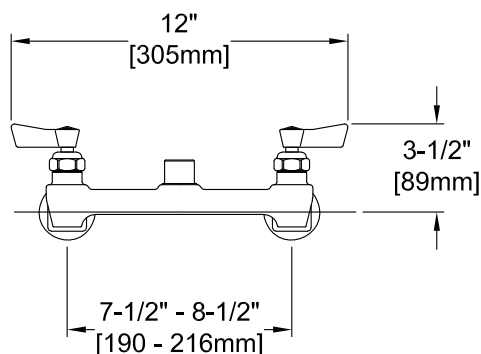

ROUGH-IN:

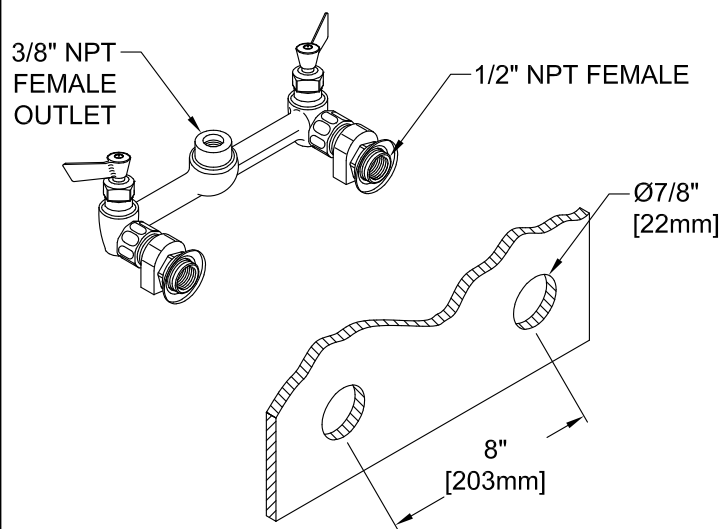

FISHER

FISHER MANUFACTURING COMPANY
TOLL FREE: 800-421-6162 - FAX: 800-832-8238
information@fisher-mfg.com - www.fisher-mfg.com