


# THROUGH-THE-WALL AIR CONDITIONER

WITH HEAT | 12,000 BTU | ELECTRONIC




**3AWTWH120002A**

<b>UPC CODE</b>	850026535150
<b>COOLING CAPACITY (BTU)</b>	12000
<b>HEATING CAPACITY (BTU)</b>	10600
<b>ENERGY STAR</b>	No
<b>COVERAGE AREA (sq. ft.)</b>	550
<b>CEER</b>	9.5
<b>VOLTAGE</b>	208/230V
<b>AMPS</b>	5.5/5.9
<b>WATTS</b>	1263/1232
<b>FAN SPEEDS (cool/fan/heat)</b>	3/3/1
<b>UNIT DIMENSIONS (W×H×D) (in.)</b>	24.25×14.25×20.25
<b>PKG. DIMENSIONS (W×H×D) (in.)</b>	28×17×27
<b>WEIGHT (Net/Gross) (lbs.)</b>	78/89
<b>CONTAINER QTY. (40HQ)</b>	306
<b>REFRIGERANT</b>	R32
<b>OUTLET CONFIGURATION</b>	 20A - 230V

## CHOOSING THE RIGHT AIR CONDITIONER

### 1 MEASURE AREA OF THE ROOM

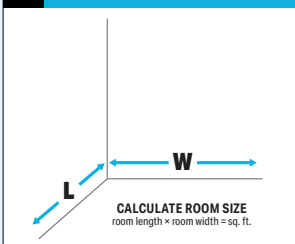

### 2 MATCH ROOM SIZE WITH CORRECT BTUs

SQ. FT.	ROOM SIZE	BTUs
150	10' × 15'	5,000
250	10' × 25'	6,000
350	17' × 20'	8,000
450	15' × 30'	10,000
550	20' × 27'	12,000
700	20' × 35'	15,000
1,000	25' × 40'	18,000
1,500	30' × 50'	25,000

### 3 MAKE ANY ADJUSTMENTS



**INCREASE BTU 10%**  
FOR SUNNY ROOMS. DECREASE  
BTU 10% FOR SHADED ROOMS.



**ADD 600 BTUs**  
FOR EACH ADDITIONAL  
PERSON OVER TWO.



**ADD 4,000 BTUs**  
IF UNIT IS USED IN  
A KITCHEN.

## FEATURES

- Fits most standard through-the-wall AC sleeves
- 3 cooling and fan speeds & 1 heat speed
- 4-way adjustable air vents
- Cool, Heat, Fan, Eco, and Sleep modes
- Quick & easy installation
- Mounting kit included
- Electronic controls
- Follow-me remote control acts as portable thermostat
- 24-hour timer
- Auto-restart
- Adjustable thermostat (62-86°F)
- Easy clean tilt-out filter

