


EXTRAFLEX®

04-007

SPECIFICATION SHEET

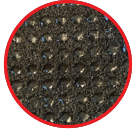

Dotted
Palm



ATTRIBUTES:

- 15g Gray Nylon Liner
- Black HCT® MicroFoam Nitrile Palm Coating With Dots

FEATURES:

- Enhanced Grip & Abrasion Resistance
- Breathable Coating for Superior Comfort

APPLICATIONS:

- General Assembly
- Automotive Assembly
- Light Manufacturing
- Maintenance
- Warehousing
- Landscaping

CATEGORY:

- Extraflex®

CARE INSTRUCTIONS:

Recommended washing temperature is between 40°C and 60°C (104 - 140°F) with mild detergent.

The drying process may cause felting on the fabric surface. Drying temperatures should not exceed 70°C (158°F).

TECHNOLOGIES:



Hybrid Coating Technology

SPECIFICATIONS:

- **Liner Materials:** 15g Gray Nylon Liner
- **Coating Materials:** Black HCT® MicroFoam Nitrile With Dots
- **Wrist Design:** Continuous Knit
- **Origin:** PRC
- **Sizes:** XS-XXL

Armor Guys Reference Number: 04-007

PACKAGING:

GLOVE SIZE	XS	S	M	L	XL	XXL
CUFF COLOR	Purple	Red	Yellow	Brown	Black	Blue
PER CASE	10DZ	10DZ	10DZ	10DZ	10DZ	10DZ
CASE WEIGHT	10.13/lbs	10.57/lbs	11.23/lbs	12.78/lbs	13.88/lbs	14.76/lbs

PERFORMANCE LEVEL:

EN388: 4131 – EN Level 1 Cut Resistance

ABRASION	0	1	2	3	4	5
CUT	0	1	2	3	4	5
TEAR	0	1	2	3	4	5
PUNCTURE	0	1	2	3	4	5

ARMOR GUYS

• PROTECTED •