

Weatherproof outlet covers

Single-gang

Applications:

- Used to provide weatherproof protection for outdoor receptacles

Features:

- Durable die cast aluminum construction for long product life
- Self-closing cover provides weatherproof protection when device not in use
- Powder paint finish for corrosive environments
- Includes gasket and hardware


Certifications and compliances:

- UL File No. E-121488
- CSA C22.2 No. 18
- Complies with NEC Article 406.9(B)(1)
- NEMA 3R



Standard materials:

- Covers – die cast aluminum
- Gaskets – polyethylene foam

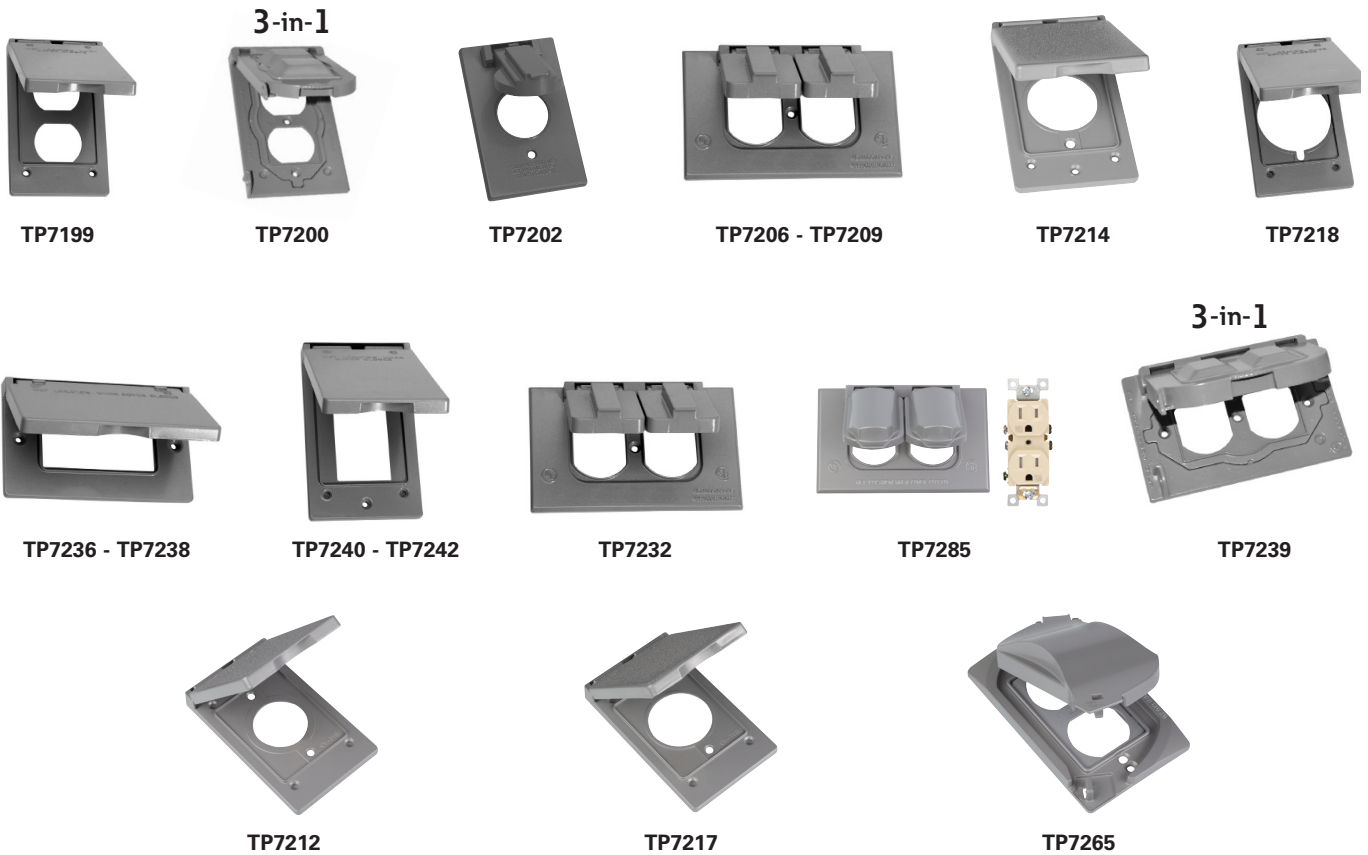

Weatherproof

Weatherproof outlet covers

Single-gang

Cat. #	Description	Color	Mounting orientation	Unit qty.	Wt. lbs. per 100
TP7199 ^A	Duplex	Gray	Vertical	50	29.3
TP7198 ^A	Duplex	White	Vertical	50	29.3
TP7197 ^A	Duplex	Bronze	Vertical	50	29.3
TP7200 ^B	GFCI, duplex, 1.38" round	Gray	Vertical	24	43.9
TP7201 ^B	GFCI, duplex, 1.38" round	White	Vertical	24	43.9
TP7205 ^B	GFCI, duplex, 1.38" round	Bronze	Vertical	24	43.9
TP7202 ^A	Single receptacle or switch, 1.425" round	Gray	Vertical	25	16.9
TP7203 ^A	Single receptacle or switch, 1.425" round	White	Vertical	25	16.9
TP7204 ^A	Single receptacle or switch, 1.425" round	Bronze	Vertical	25	16.9
TP7206 ^A	Duplex or combo switch	Natural	Horizontal	50	18.6
TP7207 ^A	Duplex or combo switch	Gray	Horizontal	50	19.2
TP7208 ^A	Duplex or combo switch	White	Horizontal	50	19.2
TP7209 ^A	Duplex or combo switch	Bronze	Horizontal	50	19.2
TP7214 ^A	Single receptacle or switch, 1.625" round	Gray	Vertical	25	30.4
TP7218 ^A	20/30/50A receptacle, 2.125" round	Gray	Vertical	25	28.6
TP7221 ^A	20/30/50A receptacle, 2.125" round	White	Vertical	25	28.6
TP7219 ^A	20/30/50A receptacle, 2.125" round	Bronze	Vertical	25	28.6
TP7232 ^A	Duplex, switch, combination device	Natural	Horizontal	50	17.9
TP7233 ^A	Duplex, switch, combination device	Gray	Horizontal	50	18.5
TP7236 ^A	GFCI	Gray	Horizontal	25	21.8
TP7237 ^A	GFCI	White	Horizontal	25	21.8
TP7238 ^A	GFCI	Bronze	Horizontal	25	21.8
TP7239 ^B	GFCI, duplex, 1.38" round	Gray	Horizontal	24	43.7
TP7245 ^B	GFCI, duplex, 1.38" round	White	Horizontal	24	43.7
TP7246 ^B	GFCI, duplex, 1.38" round	Bronze	Horizontal	24	43.7
TP7240 ^A	GFCI	Gray	Vertical	25	22.5
TP7241 ^A	GFCI	White	Vertical	25	22.5
TP7242 ^A	GFCI	Bronze	Vertical	25	22.5
TP7212 ^A	Single receptacle or switch, 1.425" round	Gray	Vertical	15	29.9
TP7217 ^A	Single receptacle or switch, 1.64" round	Gray	Vertical	15	30.0
TP7285 ^B	Duplex cover with receptacle	Gray	Horizontal	10	31.9
TP7286 ^B	Duplex cover with receptacle	White	Horizontal	10	31.9
TP7287 ^B	Duplex cover with receptacle	Bronze	Horizontal	10	31.9
TP7265 ^B	GFCI, duplex, 1.38" round	Gray	Vertical/horizontal	12	27.3
TP7267 ^B	GFCI, duplex, 1.38" round	White	Vertical/horizontal	12	27.3
TP7266 ^B	GFCI, duplex, 1.38" round	Bronze	Vertical/horizontal	12	27.3

^A UL Listed and CSA certified.

^B cULus Listed.