

### Decorator dimmers

#### Product description

Single-pole & 3-way  
 1000W/VA, 1200W/VA, or 8A; 120V/AC or 277V/AC  
 Incandescent/halogen, magnetic low-voltage, electronic low-voltage, fluorescent, compact fluorescent, LED

#### Design features

- Preset feature allows user to return to previous light setting when turning lights on
- Integrated linear slide control for easy, precise operation
- All units are available in combined single-pole/3-way versions
- Device can be wired into either 3-way location (load side or line side)
- Neutral is not required for installation of device
- Replaces a standard switch and offers dimmer capabilities
- Square law dimming—perceived dimming level is proportional to the slider position
- Power failure memory
- Electrostatic discharge protection
- Precise color matching to match room decor
- Compatible with any decorator wallplate
- Adjustable high-end trim
- Title 24 compliant



DF8AP



DF10P

#### Dimmers, back & side wire



Rating		Compatible lamp types	Description	Color suffix	Catalog no.	TITLE 24
W/AC	V/AC					
1000	120	INC, HAL, MLV	Incandescent/halogen, magnetic low-voltage dimmer, single-pole/3-way with preset	A, B, BK, GY, LA, V, W	<input type="checkbox"/> DF10P-__	•

cULus Listed to UL1472, file no. E47967; NOM certified

#### Fluorescent dimmers, back & side wire



Rating		Description	Color suffix	Catalog no.	TITLE 24
W/VA	V/AC				
1000	120	Fluorescent dimmer; single-pole/3-way with preset; Mark 10 <sup>®</sup> , AmbiStar <sup>®</sup> & Tu-Wire <sup>®</sup> compatible	A, B, BK, GY, LA, V, W	<input type="checkbox"/> DF8AP-__	•
1000	277	Fluorescent dimmer, single-pole/3-way with preset, Mark 10 <sup>®</sup> compatible	A, B, BK, GY, LA, V, W	<input type="checkbox"/> DF8AP7-__	•

cULus Listed to UL1472, file no. E47967; NOM certified

#### 0-10V Dimmer, back & side wire




Rating		Compatible lamp types	Description	Color suffix	Catalog no.	TITLE 24
Watt	V/AC					
1200	120	Dimmable LED/FLR 0-10V ballasts	Decorator dimmer, single-pole/3-way, preset	C1, C2, C4, C5	<input type="checkbox"/> DF10P-__	•
1600	277					
—	—	—	Color change faceplate for DF10P	A, BK, GY, LA, V, W	<input type="checkbox"/> DCK1-__	

cULus Listed to UL1472, file no. E47967; NOM certified

#### Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), V (Ivory), W (White), C1 (Color Change Kit: A, W, V), C2 (Color Change Kit: LA, W, V), C4 (Color Change Kit: BK, W, V), C5 (Color Change Kit: BK, W, GY)

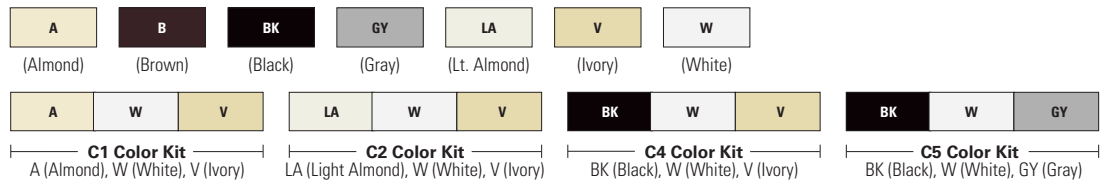


**Derating information:** G-19 **Dimensional information:** A-42 **Specification information:** Please visit [www.eaton.com/wiringdevices](http://www.eaton.com/wiringdevices)  
 Mark 10<sup>®</sup> and AmbiStar<sup>®</sup> are registered trademarks of Philips Advance; Tu-Wire<sup>®</sup> is a registered trademark of Lutron.

**Compliances, specifications and availability are subject to change without notice.**

**TITLE 24** Indicates Title 24 compliant - Page G-4


### Aspire

Family	A	B	C	D	E
<b>600W smart dimmers &amp; accessory dimmers</b> (9540-N, 9524, 9542)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.60" (66.1mm)	1.38" (35.1mm)
<b>1000W smart dimmers</b> (9536, 9537)	2.45" (62.1mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.60" (66.1mm)	1.38" (35.1mm)
<b>Slide dimmers &amp; fan speed controls</b> (9543, 9544)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.69" (68.3mm)	1.27" (32.3mm)
<b>Single-pole &amp; 3-way switches</b> (9501, 9503, 9515, 9516)	1.44" (36.6mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.74" (69.6mm)	0.97" (24.6mm)
<b>4-way switches</b> (9504)	1.44" (36.6mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.60" (66.1mm)	1.18" (30.0mm)
<b>Timers</b> (9590, 9591)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.59" (65.8mm)	1.39" (35.4mm)

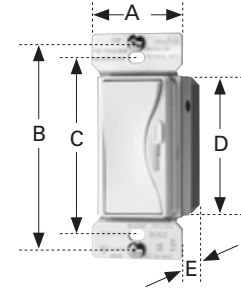


### Smart Dimmers & Timers

Family	A	B	C	D	E
<b>600W smart dimmers &amp; accessory dimmers</b> (AAL06, ARD)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.59" (65.8mm)	1.38" (35.1mm)
<b>1000W smart dimmers</b> (AIM10)	2.44" (62.0mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.59" (65.8mm)	1.38" (35.1mm)
<b>Timers</b> (PT18)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.59" (65.8mm)	1.39" (35.4mm)

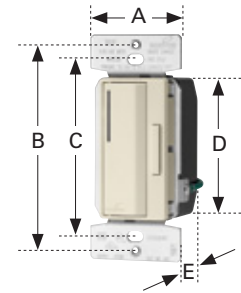


### Decorator Dimmers

Family	A	B	C	D	E
<b>600W dimmers</b> (DAL06P)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.67" (67.8mm)	1.28" (32.6mm)
<b>1000W dimmers</b> (DI10P, DF8AP7)	2.45" (62.2mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.67" (67.8mm)	1.28" (32.6mm)
<b>Fan speed controls</b> (DFS15)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.67" (67.8mm)	1.28" (32.6mm)

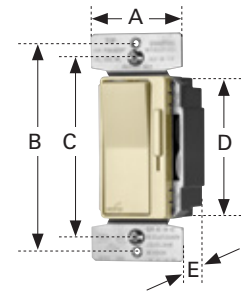


### Slide Dimmers

Family	A	B	C	D	E
<b>600W dimmers</b> (SAL06P)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.67" (67.8mm)	1.27" (32.4mm)
<b>1000W dimmers</b> (SI10P, SF8AP7)	2.45" (62.2mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.67" (67.8mm)	1.27" (32.4mm)
<b>Fan speed controls</b> (SFS15)	1.80" (45.7mm)	3.81" (96.8mm)	3.28" (83.3mm)	2.67" (67.8mm)	1.27" (32.4mm)

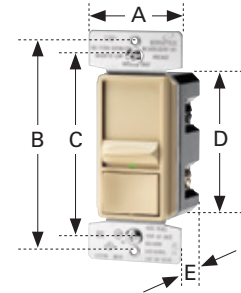


Dimmers & fan speed controls


**Aspire** 3 speed & fully variable  
Slide fan Single-pole  
9544, 9543

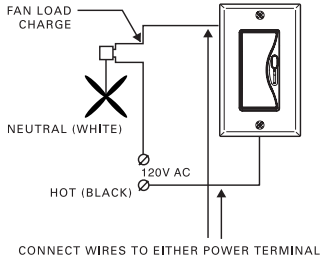


**Aspire** 3 speed & fully variable  
Slide fan 3-way  
9544, 9543

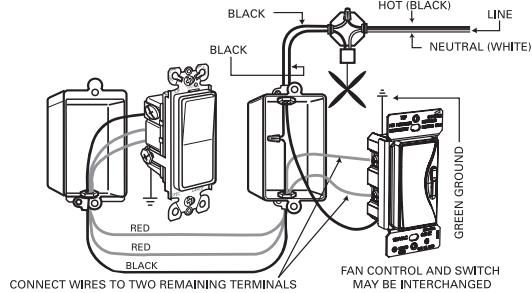


**Decorator** INC, MLV  
Dimmer & fan Single-pole  
DI10P, DFS15P

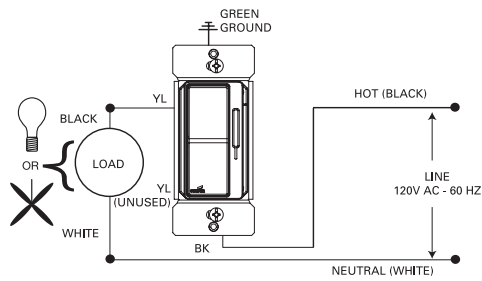


**Decorator** INC, MLV  
Dimmer & fan 3-way  
DI10P, DFS15P

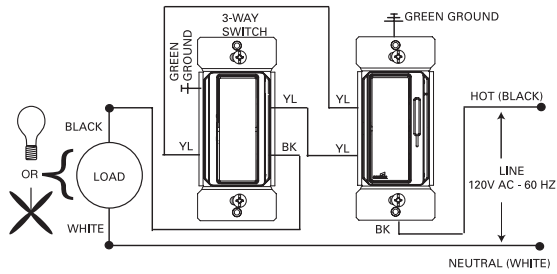


**Slide** INC, MLV  
Dimmer & fan Single-pole  
SI061, SI10P, SFS15P, SFS5P, SFS5

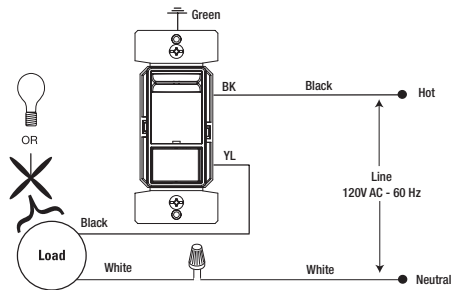

**Slide** INC, MLV  
Dimmer & fan 3-way  
SI10P, SFS15P, SFS5P, SFS5

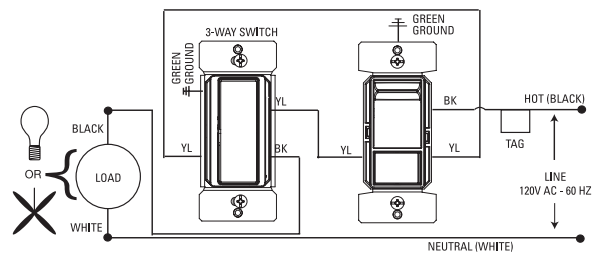

**Slide** 3 speed, INC  
Slide fan/dimmer Single-pole  
SDC15

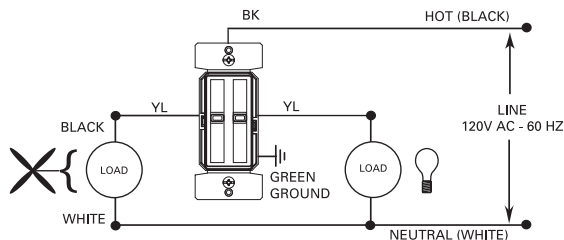

**Toggle, Rotary** Fully variable  
Toggle & rotary fan Single-pole  
TFS5, RFS5, RFS15

