



L TIMING PULLEY BAR STOCK

0.375" / 9.525 mm Pitch
Aluminum

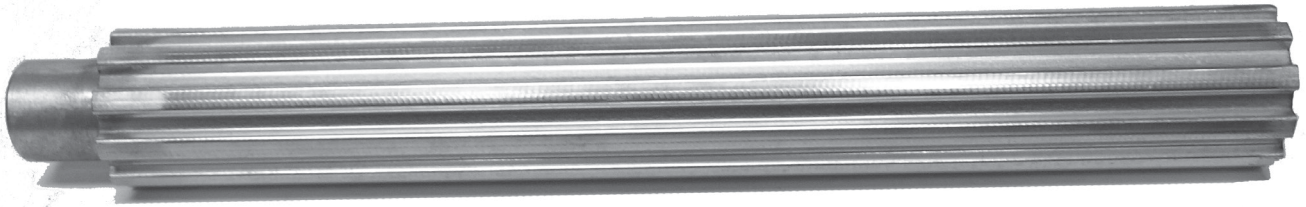

Timing Pulley Stock

Part Number	No. of Teeth	Metric		Inch		Shank Diameter	Shank Length	Minimum Usable Length	Overall Length
		Pitch Diameter	Outside Diameter	Pitch Diameter	Outside Diameter				
10L-PS8A	10	30.3 mm	29.6 mm	1.194"	1.164"	0.750"	0.750"	8.000"	8.750"
11L-PS8A	11	33.4 mm	32.6 mm	1.313"	1.283"	0.750"	0.750"	8.000"	8.750"
12L-PS8A	12	36.4 mm	35.6 mm	1.432"	1.402"	1.000"	1.000"	8.000"	9.000"
13L-PS8A	13	39.4 mm	38.7 mm	1.552"	1.522"	1.000"	1.000"	8.000"	9.000"
14L-PS8A	14	42.4 mm	41.7 mm	1.671"	1.641"	1.000"	1.000"	8.000"	9.000"
15L-PS8A	15	45.5 mm	44.7 mm	1.790"	1.760"	1.000"	1.000"	8.000"	9.000"
16L-PS8A	16	48.5 mm	47.8 mm	1.910"	1.880"	1.000"	1.000"	8.000"	9.000"
17L-PS8A	17	51.5 mm	50.8 mm	2.029"	1.999"	1.000"	1.000"	8.000"	9.000"
18L-PS8A	18	54.6 mm	53.8 mm	2.149"	2.119"	1.000"	1.000"	8.000"	9.000"
19L-PS8A	19	57.6 mm	56.8 mm	2.268"	2.238"	1.000"	1.000"	8.000"	9.000"
20L-PS8A	20	60.6 mm	59.9 mm	2.387"	2.357"	1.000"	1.000"	8.000"	9.000"
21L-PS8A	21	63.7 mm	62.9 mm	2.507"	2.477"	1.000"	1.000"	8.000"	9.000"
22L-PS8A	22	66.7 mm	65.9 mm	2.626"	2.596"	1.000"	1.000"	8.000"	9.000"
23L-PS8A	23	69.7 mm	69.0 mm	2.745"	2.715"	1.000"	1.000"	8.000"	9.000"
24L-PS8A	24	72.8 mm	72.0 mm	2.865"	2.835"	1.000"	1.000"	8.000"	9.000"
25L-PS8A	25	75.8 mm	75.1 mm	2.985"	2.955"	1.000"	1.000"	8.000"	9.000"
26L-PS8A	26	78.8 mm	78.1 mm	3.104"	3.074"	1.000"	1.000"	8.000"	9.000"
27L-PS8A	27	81.9 mm	81.1 mm	3.224"	3.194"	1.000"	1.000"	8.000"	9.000"
28L-PS8A	28	84.9 mm	84.1 mm	3.342"	3.312"	1.000"	1.000"	8.000"	9.000"

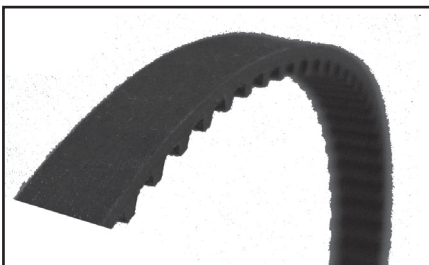

For matching
L pitch belts,
see page 194.



For L pitch
timing pulleys,
see page 30.