

# 2 MM POWERHOUSE™ BELTS

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)


**Standard Widths:**

**3 mm, 6 mm, 9 mm**

**Neoprene Construction**

**Fiberglass Reinforcements**

(Note: Custom belt widths are available upon request.)

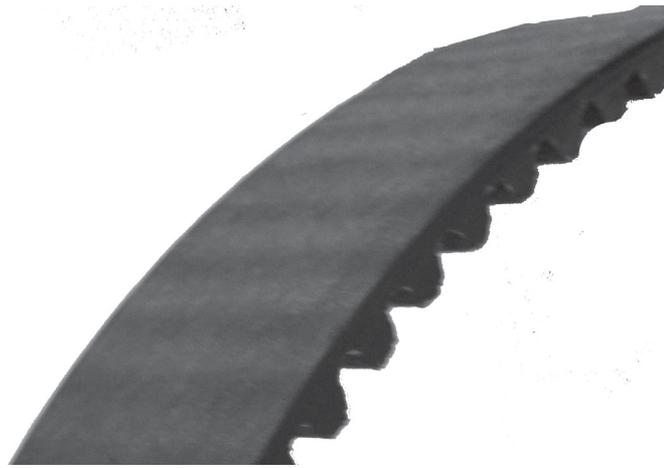

Timing Belts

| Part Number | No. of Teeth | Pitch Length (mm) |
|-------------|--------------|-------------------|
| 280-2P      | 140          | 280.0             |
| 282-2P      | 141          | 282.0             |
| 284-2P      | 142          | 284.0             |
| 286-2P      | 143          | 286.0             |
| 288-2P      | 144          | 288.0             |
| 290-2P      | 145          | 290.0             |
| 292-2P      | 146          | 292.0             |
| 294-2P      | 147          | 294.0             |
| 300-2P      | 150          | 300.0             |
| 302-2P      | 151          | 302.0             |
| 304-2P      | 152          | 304.0             |
| 308-2P      | 154          | 308.0             |
| 310-2P      | 155          | 310.0             |
| 314-2P      | 157          | 314.0             |
| 318-2P      | 159          | 318.0             |
| 320-2P      | 160          | 320.0             |
| 322-2P      | 161          | 322.0             |
| 324-2P      | 162          | 324.0             |
| 326-2P      | 163          | 326.0             |
| 328-2P      | 164          | 328.0             |
| 330-2P      | 165          | 330.0             |
| 332-2P      | 166          | 332.0             |
| 336-2P      | 168          | 336.0             |
| 338-2P      | 169          | 338.0             |
| 340-2P      | 170          | 340.0             |
| 342-2P      | 171          | 342.0             |
| 344-2P      | 172          | 344.0             |
| 346-2P      | 173          | 346.0             |
| 350-2P      | 175          | 350.0             |
| 352-2P      | 176          | 352.0             |
| 354-2P      | 177          | 354.0             |
| 356-2P      | 178          | 356.0             |
| 358-2P      | 179          | 358.0             |

| Part Number | No. of Teeth | Pitch Length (mm) |
|-------------|--------------|-------------------|
| 360-2P      | 180          | 360.0             |
| 364-2P      | 182          | 364.0             |
| 366-2P      | 183          | 366.0             |
| 370-2P      | 185          | 370.0             |
| 372-2P      | 186          | 372.0             |
| 376-2P      | 188          | 376.0             |
| 380-2P      | 190          | 380.0             |
| 382-2P      | 191          | 382.0             |
| 386-2P      | 193          | 386.0             |
| 392-2P      | 196          | 392.0             |
| 394-2P      | 197          | 394.0             |
| 400-2P      | 200          | 400.0             |
| 406-2P      | 203          | 406.0             |
| 412-2P      | 206          | 412.0             |
| 420-2P      | 210          | 420.0             |
| 426-2P      | 213          | 426.0             |
| 428-2P      | 214          | 428.0             |
| 430-2P      | 215          | 430.0             |
| 436-2P      | 218          | 436.0             |
| 440-2P      | 220          | 440.0             |
| 444-2P      | 222          | 444.0             |
| 446-2P      | 223          | 446.0             |
| 448-2P      | 224          | 448.0             |
| 452-2P      | 226          | 452.0             |
| 456-2P      | 228          | 456.0             |
| 460-2P      | 230          | 460.0             |
| 466-2P      | 233          | 466.0             |
| 470-2P      | 235          | 470.0             |
| 474-2P      | 237          | 474.0             |
| 478-2P      | 239          | 478.0             |
| 480-2P      | 240          | 480.0             |
| 484-2P      | 242          | 484.0             |
| 486-2P      | 243          | 486.0             |

| Part Number | No. of Teeth | Pitch Length (mm) |
|-------------|--------------|-------------------|
| 488-2P      | 244          | 488.0             |
| 492-2P      | 246          | 492.0             |
| 494-2P      | 247          | 494.0             |
| 500-2P      | 250          | 500.0             |
| 502-2P      | 251          | 502.0             |
| 504-2P      | 252          | 504.0             |
| 506-2P      | 253          | 506.0             |
| 516-2P      | 258          | 516.0             |
| 524-2P      | 262          | 524.0             |
| 528-2P      | 264          | 528.0             |
| 530-2P      | 265          | 530.0             |
| 534-2P      | 267          | 534.0             |
| 544-2P      | 272          | 544.0             |
| 550-2P      | 275          | 550.0             |
| 552-2P      | 276          | 552.0             |
| 558-2P      | 279          | 558.0             |
| 560-2P      | 280          | 560.0             |
| 570-2P      | 285          | 570.0             |
| 572-2P      | 286          | 572.0             |
| 576-2P      | 288          | 576.0             |
| 578-2P      | 289          | 578.0             |
| 586-2P      | 293          | 586.0             |
| 598-2P      | 299          | 598.0             |
| 600-2P      | 300          | 600.0             |
| 606-2P      | 303          | 606.0             |
| 616-2P      | 308          | 616.0             |
| 630-2P      | 315          | 630.0             |
| 634-2P      | 317          | 634.0             |
| 640-2P      | 320          | 640.0             |
| 646-2P      | 323          | 646.0             |
| 660-2P      | 330          | 660.0             |
| 670-2P      | 335          | 670.0             |
| 676-2P      | 338          | 676.0             |

Neoprene 2 mm POWERHOUSE™ timing belt part numbers can be determined as follows:  
Pitch Length Code + -2P- + Width Code