

3 MM POWERHOUSE™ BELTS

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)


Standard Widths:

6 mm, 9 mm, 15 mm

Neoprene Construction

Fiberglass Reinforcements

(Note: Custom belt widths are available upon request.)

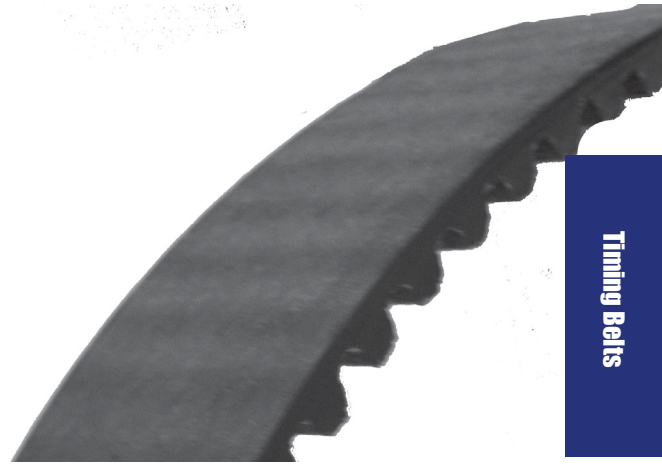

Timing Belts



Part Number	No. of Teeth	Pitch Length (mm)
99-3P	33	99.0
111-3P	37	111.0
120-3P	40	120.0
123-3P	41	123.0
129-3P	43	129.0
135-3P	45	135.0
144-3P	48	144.0
150-3P	50	150.0
159-3P	53	159.0
162-3P	54	162.0
165-3P	55	165.0
177-3P	59	177.0
180-3P	60	180.0
183-3P	61	183.0
189-3P	63	189.0
195-3P	65	195.0
201-3P	67	201.0
204-3P	68	204.0
210-3P	70	210.0
219-3P	73	219.0
225-3P	75	225.0
231-3P	77	231.0
240-3P	80	240.0
243-3P	81	243.0
246-3P	82	246.0
252-3P	84	252.0
255-3P	85	255.0

Part Number	No. of Teeth	Pitch Length (mm)
267-3P	89	267.0
270-3P	90	270.0
282-3P	94	282.0
285-3P	95	285.0
288-3P	96	288.0
291-3P	97	291.0
300-3P	100	300.0
324-3P	108	324.0
330-3P	110	330.0
339-3P	113	339.0
348-3P	116	348.0
357-3P	119	357.0
360-3P	120	360.0
363-3P	121	363.0
375-3P	125	375.0
390-3P	130	390.0
393-3P	131	393.0
399-3P	133	399.0
408-3P	136	408.0
414-3P	138	414.0
420-3P	140	420.0
444-3P	148	444.0
447-3P	149	447.0
450-3P	150	450.0
474-3P	158	474.0
480-3P	160	480.0
483-3P	161	483.0

Part Number	No. of Teeth	Pitch Length (mm)
489-3P	163	489.0
495-3P	165	495.0
501-3P	167	501.0
504-3P	168	504.0
510-3P	170	510.0
513-3P	171	513.0
537-3P	179	537.0
540-3P	180	540.0
552-3P	184	552.0
564-3P	188	564.0
570-3P	190	570.0
600-3P	200	600.0
630-3P	210	630.0
684-3P	228	684.0
696-3P	232	696.0
735-3P	245	735.0
750-3P	250	750.0
786-3P	262	786.0
840-3P	280	840.0
849-3P	283	849.0
945-3P	315	945.0
1050-3P	350	1050.0
1080-3P	360	1080.0
1272-3P	424	1272.0
1536-3P	512	1536.0
1587-3P	529	1587.0
2061-3P	687	2061.0

Neoprene 3 mm POWERHOUSE™ timing belt part numbers can be determined as follows:
Pitch Length Code + -3P- + Width Code