

2 MM OPEN ENDED

POWERHOUSE™ BELTS


(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)

Standard Widths:

4 mm, 6 mm, 9 mm

Neoprene Construction

Fiberglass Reinforcements

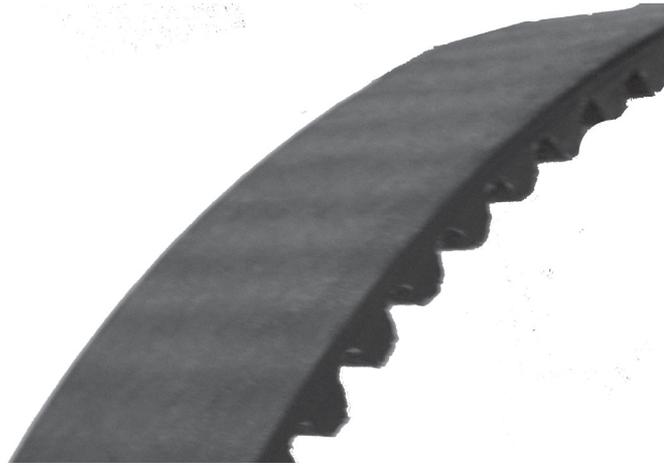

Timing Belts

Part Number	Width	Net Weight per Foot	Maximum Continuous Length
LL2P04	4 mm	.01	300 feet
LL2P06	6 mm	.01	300 feet
LL2P09	9 mm	.02	300 feet


Open ended belting is a money-saving, low upkeep alternative to roller chain and is most effective in long length conveying and positioning applications requiring protection from grime, grease, oil, and moisture.

2 MM POWERHOUSE™ CLAMPING PLATE

Standard Widths:

3 mm, 6 mm, 9 mm

Aluminum

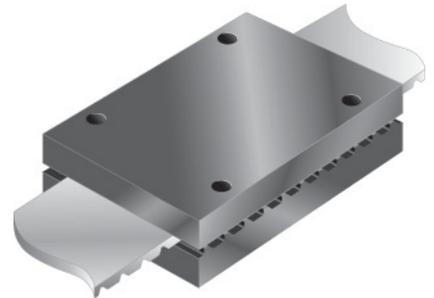

Part Number	For Belt Width (mm)
CP-2P-06	4 mm, 6 mm
CP-2P-09	9 mm



GEARED FOR SUCCESS