

3 MM OPEN ENDED POWERHOUSE™ BELTS

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)


Standard Widths:

6 mm, 9 mm, 15 mm

Neoprene Construction

Fiberglass Reinforcements

(Note: Custom belt widths are available upon request.)

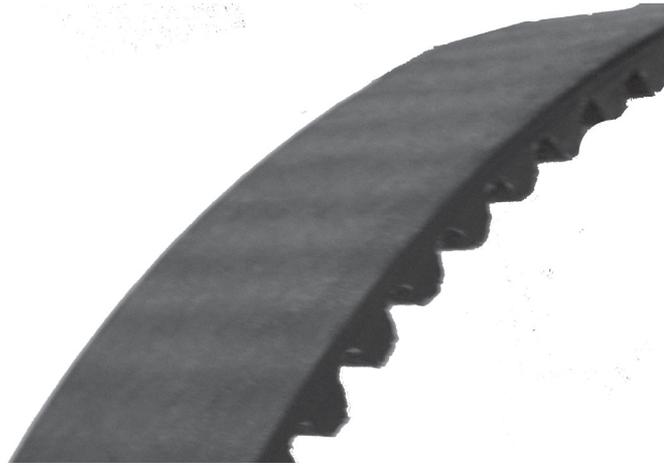

Part Number	Width	Net Weight per Foot	Maximum Continuous Length
LL3P06	6 mm	.02	600 feet
LL3P09	9 mm	.02	385 feet
LL3P15	15 mm	.04	240 feet


Open ended belting is a money-saving, low upkeep alternative to roller chain and is most effective in long length conveying and positioning applications requiring protection from grime, grease, oil, and moisture.

3 MM POWERHOUSE™ CLAMPING PLATE

Standard Widths:

6 mm, 9 mm, 15 mm

Aluminum

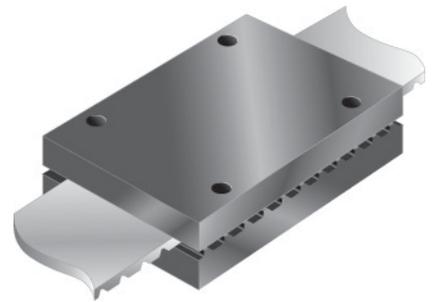

Part Number	For Belt Width (mm)
CP-3P-06	6 mm
CP-3P-09	9 mm
CP-3P-15	15 mm

Instead of doing the calculations and referencing dozens of pages of belt length tables, visit our website at www.bbman.com to take advantage of the convenience of our easy-to-use Belt Length Calculator.

It is a free service designed to be a clear, accessible, and quick tool to choose a belt to fit your needs. Simply choose your pitch, belt width, pulley tooth counts, and center to center distance of the pulleys and the calculator will give you the part number and specifications of the timing belt that you need.