


5 MM OPEN ENDED POWERHOUSE™ BELTS

(Compatible with PowerGrip® GT2® and PowerGrip® GT3® pitches)

Standard Widths:

9 mm, 15 mm

Neoprene Construction
Fiberglass Reinforcements

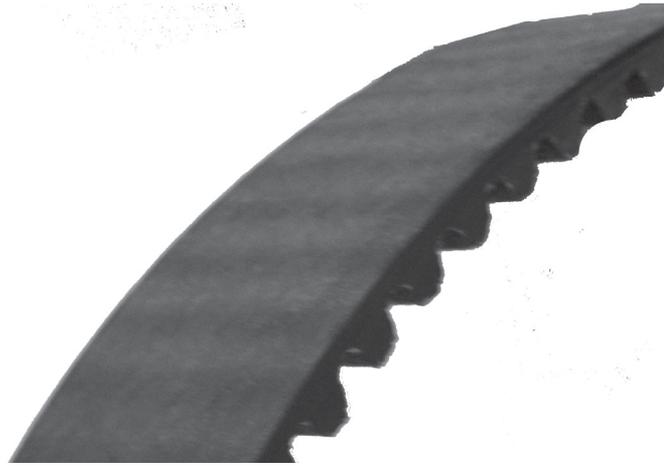

Part Number	Width	Net Weight per Foot	Maximum Continuous Length
LL5P09	9 mm	.03	360 feet
LL5P15	15 mm	.04	230 feet

Open ended belting is a money-saving, low upkeep alternative to roller chain and is most effective in long length conveying and positioning applications requiring protection from grime, grease, oil, and moisture.

5 MM POWERHOUSE™ CLAMPING PLATE

Standard Widths:

9 mm, 15 mm

Aluminum



Part Number	For Belt Width (in)
CP-5P-09	0.250"
CP-5P-15	0.375"

Do you need multiple delivery dates throughout the year? Contact our sales engineers to discuss blanket order options to take advantage of quantity discounts. Blanket orders satisfy recurring requirements, save time and reduce administrative costs by eliminating repetitive purchase orders, permit purchasing to leverage buying power through volume purchasing, and reduce procurement lead time, especially for parts not commonly held in stock.

Blanket orders save you from having to hold greater than necessary amounts of stock, save you the trouble and expense of processing frequent purchase orders, and reduce the lead time required for recurring orders.