



BOBBI 10 / 12

FLUSH MOUNT CEILING

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Flush-mounted round ceiling luminaires, featuring handcrafted glass.

LAMPING

Standard: 60W A19 120V incandescent, lamp not included. Dimmable with standard incandescent dimmer (not included).

LED: 10W Integrated source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 750 lumens, 30,000 hours, included. (For Bobbi 10 only)

LED: 17W Integrated source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 1200 lumens, 30,000 hours, included. (For Bobbi 12 only)

DIFFUSER

Handcrafted glass diffuser is available in Marble decor.

Bobbi 10 #9111: 10" Dia. x 4.25" H

Bobbi 12 #9110: 12" Dia. x 5.25" H

CONSTRUCTION

Glass diffuser is secured to fitter with three set screws.

Stamped aluminum fitter is powder coated white.

MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture.

90°C supply wire required for incandescent lamping.


LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



BOBBI CEILING SHOWN IN OPAL CUT

Bobbi 10: #9111

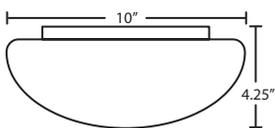


DECOR	LAMP OPTIONS	OPTIONS
911152C 10.0" Dia. Marble	(blank) 1x 60W A19 Incan	LW Low
911110C 10.0" Dia. Opal Cut	LED 10W LED, 750 lumens	Wattage labeling

MARBLE



Bobbi 12: #9110

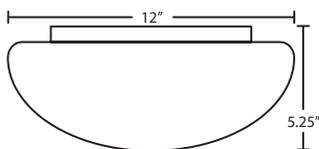

DECOR	LAMP OPTIONS	OPTIONS
911052C 12.0" Dia. Marble	(blank) 2x 60W A19 Incan	LW Low
911010C 12.0" Dia. Opal Cut	LED 17W LED, 1200 lumens	Wattage labeling

Ex. 911052C
Bobbi 12 Ceiling w/ Marble Glass

Project Information:

Empty box for project information.

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.