



BOCA 3 / 5

12V MINI PENDANTS

location:  
**DRY**

**SPECIFICATIONS:**

**DESCRIPTION**

Low voltage mini pendant with glass diffuser.

**LAMPING**

**Standard:** 35W Low pressure halogen GY6.35 12V Bi-Pin lamp, lamp included. Suitable for use in an open fixture.

**LED:** 3W Replaceable 12V LED, dimmable, 90+ CRI, 3000°K CCT, 300 lumens, 25,000 hours. Lamp included.

**DIFFUSER**

Globe-shaped shade shall be clear solid formed glass with either bubble or non-bubble décor. The inner portion is frosted to conceal the light source.

**Boca 3:** 3.15" Dia. x 3" H

**Boca 5:** 4.75" Dia. x 4.5" H

**CORD**

Standard cord is 10' field-adjustable coaxial type with teflon jacket and decorative sleeve at the socketholder. Jacket tint coordinates with metal finish.

**STANDARD PENDANT (1XC, 1XT, X)**

Mini pendant comes complete with either dome-style or flat-style canopy. See next page for multi light options with "X" prefix. Dimmable with ELV dimmers.

**QUICK-CONNECT OPTION (XP, RXP, 1XP)**


Quick-Connect Jack is compatible with Besa Rail Adapter, or Quick-Connect canopies (order separately).

**METAL FINISH**

Glass retainer hardware, sleeve and canopies are finished in either Bronze or Satin Nickel.

**LABELS**

UL or ETL Listed. Suitable for Dry Locations (interior use only).

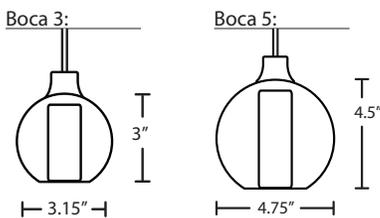

CLEAR (BOCA5CL) & CLEAR BUBBLE (BOCA3BB)



**Project Information:**

**For ordering information, see next page**

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

**REV 12/18**



ORDERING:

CONNECTION	GLASS OPTIONS	LAMP OPTIONS	METAL FINISH	OPTIONS
Quick-Connect	<b>BOCA3BB</b> 3.15" Clear Bubble	(blank) 35W Hal	<b>BR</b> Bronze	<b>L</b> 15' cord
<b>XP</b> Jack Only	<b>BOCA3CL</b> 3.15" Clear	<b>LED</b> 3W LED	<b>SN</b> Satin Nickel	<b>277</b> 277V
<b>RXP</b> Rail-Ready	<b>BOCA5BB</b> 4.75" Clear Bubble			<b>DIM010</b> 0-10V Dimming
<b>1XP</b> Flat Canopy	<b>BOCA5CL</b> 4.75" Clear			

Pendant Fixtures

- 1XC** Dome Canopy
- 1XT** Flat Canopy

Multi light

- X** For Multi light Canopy

 


Multilight Canopies Available, see page right

**Ex. 1XT-BOCA5CL-LED-SN**  
Boca 5 LED Pendant, Clear Shade, Satin Nickel Finish


QUICK-CONNECT OPTIONS:

**XP** PENDANT ELEMENT ONLY




- Pendant Shade and Cord/Socket Set
- 10' Field-adjustable braided coaxial-type cord with a teflon jacket (clear or bronze tint coordinates with metal finish)
- Quick-Connect Jack provided
- Compatible with Besa Canopies and Rail Adapter
- Bronze or Satin Nickel metal finishes

 **RXP** PENDANT + RAIL ADAPTER



- READY FOR RAIL**
- Pendant Shade and Cord/Socket Set, plus Rail Adapter
  - 10' Field-adjustable braided coaxial-type cord with a teflon jacket (clear or bronze tint coordinates with metal finish)
  - Quick-Connect Jack provided
  - Compatible with Besa Monorail System
  - Bronze or Satin Nickel metal finishes

 
**1XP** PENDANT + MONOPOINT FLAT CANOPY



- Pendant Shade and Cord/Socket Set, plus Flat Canopy
- 1x electronic 60W dimmable transformer, fits partially in junction box
- 10' Field-adjustable braided coaxial-type cord with a teflon jacket (clear or bronze tint coordinates with metal finish)
- Quick-Connect Jack provided
- Integral Quick-Connect adapter
- Bronze or Satin Nickel metal finishes


FIXED PENDANT OPTIONS:

 **1XC** 1 LIGHT PENDANT, DOME CANOPY




- NO CORD CUTTING REQUIRED**
- Suitable for use on sloped ceilings
  - 1x electronic 60W dimmable 120V transformer
  - Installs to standard 4" octagonal junction box
  - Bronze or Satin Nickel metal finishes

 **1XT** 1 LIGHT PENDANT, FLAT CANOPY



- Suitable for use on sloped ceilings
- 1x electronic 60W dimmable 120V transformer, fits partially in junction box
- Installs to standard 4" octagonal junction box
- Bronze or Satin Nickel metal finishes

 
**X** 1 LIGHT PENDANT FOR MULTIPOINT CANOPIES



- Suitable for use on sloped ceilings
- 1x electronic 60W dimmable 120V transformer, fits partially in junction box
- Installs to standard 4" octagonal junction box
- Bronze or Satin Nickel metal finishes


MULTIPOINT CANOPY OPTIONS:

 **T23X** 3 LIGHT ROUND CANOPY




- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 10" Dia. shades MAX, with staggered heights

 **T23XL** 3 LIGHT LARGE ROUND CANOPY




- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 16" Dia. shades MAX, with staggered heights

 **T26X** 6 LIGHT ROUND CANOPY




- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 10" Dia. shades MAX, with staggered heights

 **T29X** 9 LIGHT ROUND CANOPY




- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 10" Dia. shades MAX, with staggered heights

 **T23V** 3 LIGHT BAR CANOPY




- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 20" Dia. shades MAX, with staggered heights

 **T24V** 4 LIGHT BAR CANOPY



- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 20" Dia. shades MAX, with staggered heights

**T27V** 7 LIGHT BAR CANOPY

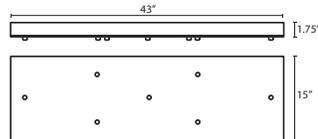

- Suitable for sloped ceilings
- Bronze or Satin Nickel
- 14" Dia. shades MAX, with staggered heights

HOW TO ORDER A MULTILIGHT FIXTURE

Order your canopy with the selected 12V multi light pendants (indicated by "X" prefix) for the complete fixture:

**Example: 1x T23XL-SN (3 Light Large Round Canopy)**

**1x X-BOCA5BB-SN (Boca 5 Pendant in Clear Bubble)**

**1x X-BOCA5CL-SN (Boca 5 Pendant in Clear)**

**1x X-BOCA5BB-SN (Boca 5 Pendant in Clear Bubble)**

CORD LENGTH OPTIONS:

**15Ft. CORD LENGTH:**

For longer 15' cord, add an "L" to the end of the item number, i.e. 1XP-174352-SNL.