



BRELLA

MINI SCONCES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted sconce featuring one handcrafted glass.

LAMPING

Standard: 40W Low-pressure G9 Halogen 120V lamp, included.

Suitable for use in an open fixture. *(Incandescent dimmer is suitable for dimming, not included)*

LED: 5W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 450 lumens, 25,000 hours, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors.

Diameter of 6.0" and height of 4.0"

CONSTRUCTION

Fixture utilizes metal arm assembly with stamped steel canopy and faceplate (5" Circle or Square), with plated finish.

METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.


MOUNTING

Installs directly to a 4" octagonal outlet box. Wall-mount only.

Designed for uplighting, but may also be oriented downward.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

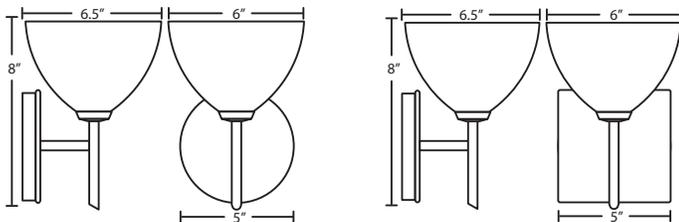

ORDERING:

FIXTURE	GLASS OPTIONS	METAL FINISH	METAL FINISH	OPTIONS
1SW Sconce	467907 White	(blank) 40W G9 Hal	BR Bronze	SQ Square
	467952 Marble	LED 5W LED 120V,	CR Chrome	Canopy
	467983 Mocha	dimmable	SN Satin Nickel	
	4679CH Cherry			
	4679KR Chalk			
	4679OK Oak			
	4679SL Solare			
	4679TN Titan			


Ex. 1SW-467983-SN

Brella Mini Sconce w/ Mocha Glass, Satin Nickel Finish

Project Information:



BRELLA SHOWN IN CHERRY (4679CH) IN BRONZE FINISH & OAK (4679OK) WITH SQUARE CANOPY

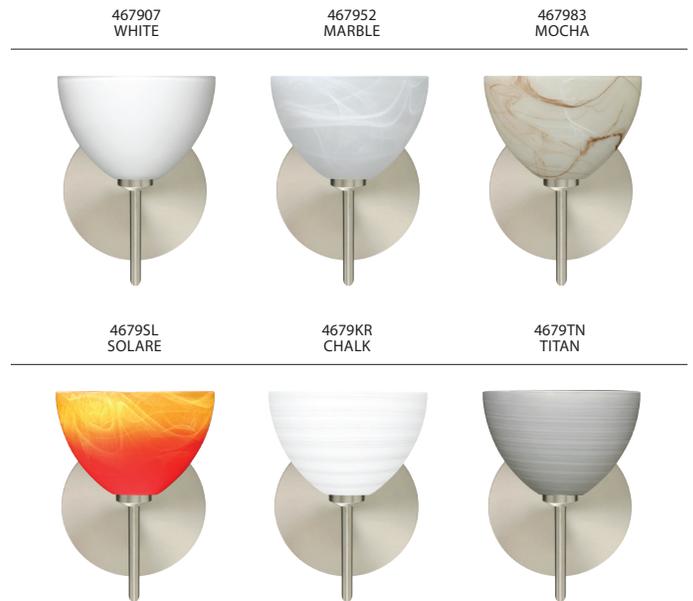

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 7/22