



CRUISE

WALL PENDANT

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted cord pendant featuring cylindrical glass shade with pressed optical ovals.

LAMPING

Standard: 60W T10 Medium-based 120V incandescent, suitable for dimming, lamp not included. *(Incandescent dimmer is suitable for dimming, not included)*

LED Edison: 4W Replaceable LED Filament T-shape lamp, 120V, CL dimmable, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors. 4.7" Dia. x 6.85" H

CONSTRUCTION

Plated steel backplate and cord support arm/loop in Bronze or Satin Nickel. Adjustable 10' cord provided.

METAL FINISH

Fixture shall be finished in Bronze or Satin Nickel.

MOUNTING


Installs directly to a 4" octagonal outlet box. Wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SMOKE (CRUSSM)

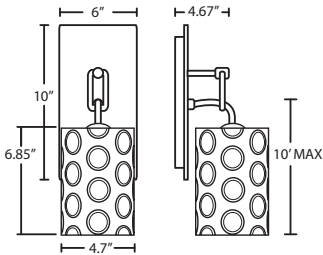

CRUSAM
AMBER

CRUSCL
CLEAR



ORDERING:

FIXTURE	SHADE OPTIONS	LAMP OPTIONS	METAL FINISH
1WP Wall Pendant	CRUSAM Amber CRUSCL Clear CRUSSM Smoke	(blank) 60W T10 Incan EDIL 4W LED Filament	BR Bronze SN Satin Nickel

Ex. 1WP-CRUSAM-SN
Cruise Wall, Amber, Satin Nickel Finish

Project Information:

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 8/21