



DIVI

MINI SCONCES WALL

location: **DAMP**

**SPECIFICATIONS:**

**DESCRIPTION**

Wall-mounted sconce featuring one handcrafted glass.

**LAMPING**

**Standard:** 40W Low-pressure G9 Halogen 120V lamp, included.

Suitable for use in an open fixture. (Incandescent dimmer is suitable for dimming, not included)

**LED:** 5W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 450 lumens, 25,000 hours, lamp included.

**DIFFUSER**

Shade shall be handcrafted glass of various decors.

Diameter of 3.375" and height of 2.625"

**CONSTRUCTION**

Fixture utilizes metal arm assembly with stamped steel canopy and faceplate (5" Circle or Square), with plated finish.

**METAL FINISH**

Fixture shall be finished in Bronze, Chrome or Satin Nickel.


**MOUNTING**

Installs directly to a 4" octagonal outlet box. Wall-mount only.

Designed for uplighting, but may also be oriented downward.

**LABELS**

UL or ETL Listed. Suitable for Damp Locations (interior use only).

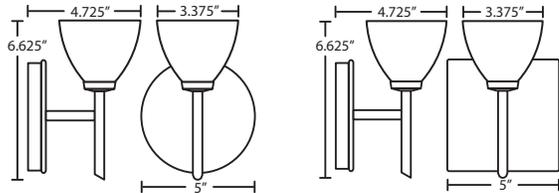

DIVI SHOWN IN CARRERA (185819) IN CHROME FINISH & GOLD FOIL (1758GF) IN CHROME FINISH

**ORDERING:**

FIXTURE	GLASS OPTIONS	METAL FINISH	METAL FINISH	OPTIONS
15W Sconce	1758CF Copper Foil 1758GF Gold Foil 1758SF Silver Foil	(blank) 40W G9 Hal LED 5W LED 120V, dimmable	BR Bronze CR Chrome SN Satin Nickel	SQ Square Canopy
	185807 Opal Matte 185819 Carrera 1858DW Black Dicro Wavy 1858VB Black Dicro Vine			

**Ex. 15W-1858SW-SN**

Divi Mini Sconce w/ Silver Dicro Wavy Glass, Satin Nickel Finish

Project Information:



All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18