



DIVI

VANITIES WALL



location:
DAMP

SPECIFICATIONS:

DESCRIPTION

2-4 light vanity luminaires featuring handcrafted glass.

LAMPING

Standard: 40W Low-pressure G9 Halogen, 120V, lamp included. Suitable for use in an open fixture. Dimmable with standard incandescent dimmer (not included).

LED: 5W Replaceable source, 120V, dimmable, 90+ CRI, 3000° K CCT, 450 lumens, 25,000 hours, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors.

Diameter of 3.375" and height of 2.625", spaced 7.875" apart on center.

CONSTRUCTION

Fixture utilizes metal arm assembly and stamped steel body, with plated finish.

Decorative finials can be removed for downlighting applications. Decorative outlet box cover optional when not required.

METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.

MOUNTING

Installs directly to a 4" octagonal outlet box, with 1.75" left or right offset. Canopy allows direct wiring without outlet box, where armored cable or non-metallic sheathed cable is employed, and the decorative outlet box cover is not required. Orient upward or downward, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



DIVI SHOWN IN SILVER DICRO WAVY (1858SW)


185807
OPAL MATTE



185819
CARRERA



1758CF
COPPER FOIL

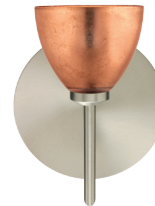

1758GF
GOLD FOIL



1758SF
SILVER FOIL



1858VB
BLACK DICRO VINE



For ordering information, see next page


All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18





ORDERING:

| FIXTURE | GLASS OPTIONS | METAL FINISH | METAL FINISH | OPTIONS |
|--------------------|-------------------------|---------------------------|-----------------|-----------|
| 2SW 2 Light Vanity | 1758CF Copper Foil | (blank) 40W G9 Hal | BR Bronze | SQ Square |
| 3SW 3 Light Vanity | 1758GF Gold Foil | LED 5W LED 120V, dimmable | CR Chrome | Canopy |
| 4SW 4 Light Vanity | 1758SF Silver Foil | | SN Satin Nickel | |
| | 185807 Opal Matte | | | |
| | 185819 Carrera | | | |
| | 1858DW Black Dicro Wavy | | | |
| | 1858VB Black Dicro Vine | | | |

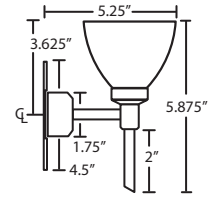

Ex. 3SW-1858DW-SN
 Divi 3-Light Vanity w/ Black Dicro Wavy Glass,
 Satin Nickel Finish

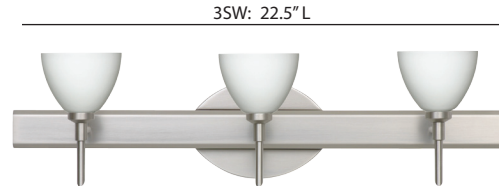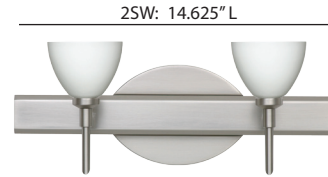

Canopy allows direct wiring without outlet box, where armored cable or non-metallic sheathed cable is employed, and the decorative outlet box cover is not required. Orient upward or downward, wall-mount only.

Project Information: