



DUKE

MINI SCONCES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted sconce featuring handcrafted clear cylinder glass with foil applique.

LAMPING

Standard: 60W T10 Medium-based 120V incandescent, suitable for dimming, lamp not included. (*Incandescent dimmer is suitable for dimming, not included*)

LED Filament: 4W Replaceable T-Style LED Filament lamp, 120V, dimmable, 3000°K CCT, 90+ CRI, 350 lumens, 15,000 hours, lamp included.

DIFFUSER

Shades shall be handcrafted in clear cylinder glass with foil applique in various decors.

CONSTRUCTION

Fixture utilizes gooseneck arm assembly and stamped steel canopy (6" H), with plated metal finish.

METAL FINISH

Fixture shall be finished in Black.

MOUNTING


Installs directly to a 4" octagonal outlet box. Orient upward or downward, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



COPPER FOIL (DUKECF)

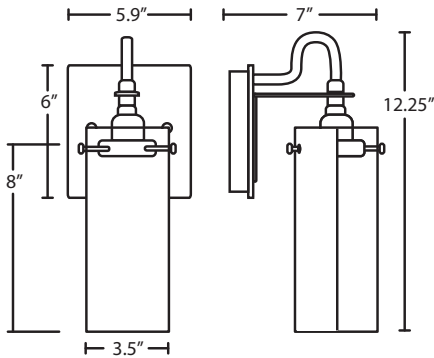

DUKEGF
GOLD FOIL

DUKESF
SILVER FOIL



ORDERING:

FIXTURE	GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
1WG Sconce	DUKECF Copper Foil DUKEGF Gold Foil DUKESF Silver Foil	(blank) 60W T10 Incan EDIL 4W LED Filament	BK Black

Ex. 1WG-DUKECF-BK
Duke Vanity, Copper Foil Glass,
Black Finish

Project Information:

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 8/21