



HOPE

SCONCES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted sconce featuring texture/clear glass shade.

LAMPING

LED: 5W Replaceable source, 120V, 90+ CRI, 3000°K CCT, 600 lumens, 30,000 hours.

DIFFUSER

Clear textured glass fused with Clear glass and an inner Opal glass.
8.75" Dia. x 4" D

CONSTRUCTION


Steel fitter in Brushed Brass or Black with match decorative cap.

MOUNTING

Installs directly to a 4" octagonal outlet box. Wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

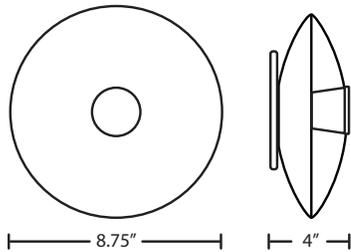

HOPECL (TEXTURE/CLEAR WITH INNER OPAL)

HOPECL-LED-BK
TEXTURE/CLEAR WITH INNER OPAL

ORDERING:

DECOR	- LAMP OPTIONS -	METAL FINISH
HOPECL Texture/Clear with Inner Opal	LED 5W LED 3000K	BB Brushed Brass BK Black

Ex. HOPECL-LED-BK
Hope Sconce, Texture/Clear Shade,
Black Finish



Project Information:
Project Information:

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.