



HOPPI

MINI SCONCES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted sconce featuring one handcrafted glass.

LAMPING

Standard: 40W Low-pressure G9 Halogen 120V lamp, included.

Suitable for use in an open fixture. *(Incandescent dimmer is suitable for dimming, not included)*

LED: 5W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 450 lumens, 25,000 hours, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors.

7.5" L x 5.5"W x 2.75" H (Asymmetric)

CONSTRUCTION

Fixture utilizes metal arm assembly with stamped steel canopy and faceplate (5" Circle or Square), with plated finish.

METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.

MOUNTING

Installs directly to a 4" octagonal outlet box. Wall-mount only.


Designed for uplighting, but may also be oriented downward.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



HOPPI SHOWN IN MOCHA/CLEAR (181305) WITH SQUARE CANOPY IN CHROME FINISH & MARBLE/CLEAR (181304)

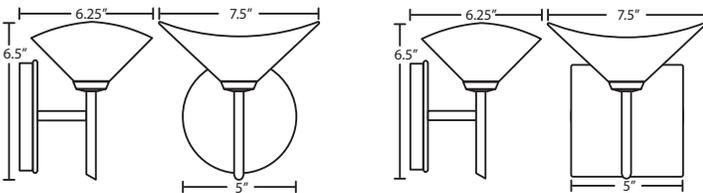

191352
MARBLE

191383
MOCHA

ORDERING:

| FIXTURE | GLASS OPTIONS | METAL FINISH | METAL FINISH | OPTIONS |
|------------|---------------------|--------------------|-----------------|-----------|
| 1SW Sconce | 181304 Marble/Clear | (blank) 40W G9 Hal | BR Bronze | SQ Square |
| | 181305 Mocha/Clear | LED 3W LED 120V, | CR Chrome | Canopy |
| | 191352 Marble | dimnable | SN Satin Nickel | |
| | 191383 Mocha | | | |

Ex. 1SW-191352-SN

Hoppi Mini Sconce w/ Marble Glass,
Satin Nickel Finish

Project Information:

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18