



# KENO

VANITIES WALL

location:  
**DAMP**

## SPECIFICATIONS:

### DESCRIPTION

1-4 light vanity luminaires featuring handcrafted bullnose shaped glass shade(s) and internal sand finish.

### LAMPING

**Standard:** 60W G9 Halogen 120V, suitable for dimming, lamp included.

**LED:** 3W Replaceable source, 120V, dimmable, 90+ CRI, 3000° K CCT, 300 lumens, 30,000 hours, lamp included.

### DIFFUSER

Shade shall be handcrafted glass with sand applied on inner glass, in various decors. 4.25" Dia. x 3" H

### CONSTRUCTION

Backplate and Bar are plated steel with option of Wood backplate accessory (see ordering on next page).

### METAL FINISH

Fixture shall be finished in Bronze or Satin Nickel.

### MOUNTING

Installs directly to a 4" octagonal outlet box. Wall-mount only.

### LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SMOKE SAND (KENOSM)

KENOGD  
GOLD SAND

KENOWH  
WHITE SAND



**For ordering information, see next page**

All dimensions provided are nominal.  
Allowance must be made for dimensional tolerance in handcrafted glasses.


**REV 1/22**



**ORDERING:**

FIXTURE	GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
1WF 1 Lt. Sconce	KENOGD Gold Sand	(blank) 60W G9 Hal	BR Bronze
2WF 2 Lt. Vanity	KENOSM Smoke Sand	LED 3W LED	SN Satin Nickel
3WF 3 Lt. Vanity	KENOWH White Sand		
4WF 4 Lt. Vanity			

**Ex. 3WF-KENOSM-SN**  
Keno Vanity, Smoke Sand Shade,  
Satin Nickel Finish

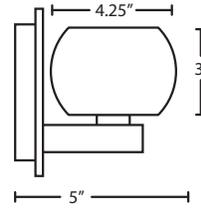

**WOOD BACKPLATE ACCESSORY - WEATHERED WOOD OR EBONY**

- S1003-WW or EB 1 Light Wood Plate, Weathered Wood (WW) or Ebony (EB)
- S1004-WW or EB 2 Light Wood Plate, Weathered Wood (WW) or Ebony (EB)
- S1005-WW or EB 3 Light Wood Plate, Weathered Wood (WW) or Ebony (EB)
- S1006-WW or EB 4 Light Wood Plate, Weathered Wood (WW) or Ebony (EB)

1WF: 5.5" L




2WF: 14" L



3WF: 22" L



4WF: 30" L

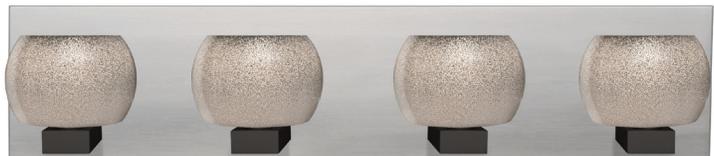

**Project Information:**

Empty box for project information.