



LASSO

VANITIES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

2-4 light vanity luminaires featuring handcrafted glass.

LAMPING

Standard: 40W Low-pressure G9 Halogen, 120V, lamp included. Suitable for use in an open fixture. Dimmable with standard incandescent dimmer (not included).

LED: 5W Replaceable source, 120V, dimmable, 90+ CRI, 3000° K CCT, 450 lumens, 25,000 hours, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors.
4.75" Dia. x 3.0" H, spaced 7.875" apart on center.

CONSTRUCTION

Fixture utilizes metal arm assembly and stamped steel body, with plated finish. Decorative finials can be removed for downlighting applications. Decorative outlet box cover optional when not required.

METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.

MOUNTING

Installs directly to a 4" octagonal outlet box, with 1.75" left or right offset. Canopy allows direct wiring without outlet box, where armored cable or non-metallic sheathed cable is employed, and the decorative outlet box cover is not required. Orient upward or downward, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



LASSO SHOWN IN GLITTER (5612GL) IN CHROME FINISH

561207
OPAL MATTE



5612GD
GOLD GLITTER



For ordering information, see next page

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18




ORDERING:

FIXTURE	-	GLASS OPTIONS	-	METAL FINISH	-	METAL FINISH	-	OPTIONS
2SW	2 Light Vanity	561207	Opal Matte	(blank)	40W G9 Hal	BR	Bronze	SQ Square
3SW	3 Light Vanity	5612GD	Gold Glitter	LED	5W LED 120V,	CR	Chrome	Canopy
4SW	4 Light Vanity	5612GL	Glitter		dimmable	SN	Satin Nickel	

Ex. 3SW-5612GL-SN

Lasso 3-Light Vanity w/ Glitter Glass, Satin Nickel Finish

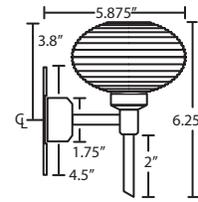

2SW: 14.625" L



3SW: 22.5" L



4SW: 30.375" L



Canopy allows direct wiring without outlet box, where armored cable or non-metallic sheathed cable is employed, and the decorative outlet box cover is not required. Orient upward or downward, wall-mount only.

Project Information: