



MILO 4

VANITIES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

2-3 light vanity luminaires featuring handcrafted ball jar glass.

LAMPING

Standard: 60W A19 Medium-based 120V incandescent, suitable for dimming, lamp not included. (*Incandescent dimmer is suitable for dimming, not included*)

Edison: 40W Edison Filament Medium-based, 120V, lamp included.

LED Filament: 7W Replaceable S-Style LED Filament lamp, 120V, dimmable, 2200°K CCT, 540 lumens, 15,000 hours, lamp included.

DIFFUSER

Shades shall be handcrafted glass of various decors.

3.75" Dia. x 6.5" H, spaced 8" apart on center.

CONSTRUCTION

Fixture utilizes gooseneck arm assembly and stamped steel canopy (6" H), with plated metal finish.

METAL FINISH

Fixture shall be finished in Black.

MOUNTING

Installs directly to a 4" octagonal outlet box. Orient upward or downward, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SMOKE (MILO4SM)

MILO4AM
AMBER

MILO4GR
GREEN

MILO4PL
PURPLE

MILO4WF
WHITE FROST



For ordering information, see next page

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.


REV 12/18



ORDERING:

FIXTURE	GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
2WG 2-Light	MILO4AM Amber	(blank) 60W A19 Incan	BK Black
3WG 3-Light	MILO4GR Green	EDI 40W Edison	
	MILO4PL Purple	EDIL 7W LED Filament	
	MILO4SM Smoke		
	MILO4WF White Frost		

Ex. 2WG-MILO4PL-BK
Milo 4 Vanity, Purple Glass,
Black Finish

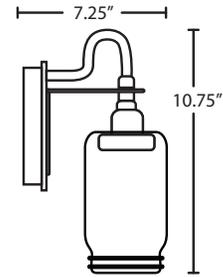

2WG: 12.25" L



3WG: 20" L



Project Information: