



# NICO 5

MINI SCONCES WALL

location:  
**DAMP**

## SPECIFICATIONS:

### DESCRIPTION

Wall-mounted sconce featuring one handcrafted glass.

### LAMPING

**Standard:** 60W A15 or A19 120V incandescent, suitable for dimming, lamp not included. (*Incandescent dimmer is suitable for dimming, not included*)

**LED:** 9W Replaceable LED source, 120V, dimmable, 90+ CRI, 2800°K CCT, 800 lumens, 30,000 hours, lamp included.

### DIFFUSER

Shade shall be handcrafted glass of various decors.

### CONSTRUCTION

Fixture utilizes die-cast arm assembly and stamped steel canopy (4.75" H), with plated metal finish.

### METAL FINISH


Fixture shall be finished in Bronze, Chrome or Satin Nickel.

### MOUNTING

Installs directly to a 4" octagonal outlet box. Orient upward or downward, wall-mount only.

### LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

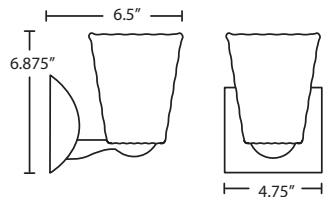

NICO 5 SHOWN IN GLITTER STONE (NIC05GL)

NIC05CL  
CLEAR STONE

## ORDERING:

FIXTURE	GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
1WZ Sconce	NIC05CL Clear Stone NIC05GL Glitter Stone	(blank) 60W Incan LED 9W LED	BR Bronze CR Chrome SN Satin Nickel

**Ex. 1WZ-NIC05CL-SN**  
Nico 5 Mini Sconce, Clear Stone Glass,  
Satin Nickel Finish



**Project Information:**

All dimensions provided are nominal.  
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18